


# Governors

Certified by TÜV to EN81 and 95/16/EC



## LK315 – bidirectional with 315 mm diameter sheave

Part Number	Rope Diameter mm	Nominal Speed m/sec	Trip Speed m/sec	Weight kg
LK315 RL 0,42	8.0 - 10.0	2.81	0.42	14
LK315 RL 0,56	8.0 - 10.0	2.81	0.56	14
LK315 RL 0,70	8.0 - 10.0	2.81	0.70	14
LK315 RL 0,84	8.0 - 10.0	2.81	0.84	14
LK315 RL 0,92	8.0 - 10.0	2.81	0.92	14
LK315 RL 1,00	8.0 - 10.0	2.81	1.00	14
LK315 RL 1,13	8.0 - 10.0	2.81	1.13	14
LK315 RL 1,26	8.0 - 10.0	2.81	1.26	14
LK315 RL 1,40	8.0 - 10.0	2.81	1.40	14
LK315 RL 1,60	8.0 - 10.0	2.81	1.60	14
LK315 RL 2,00	8.0 - 10.0	2.81	2.00	14
LK315 RL 2,25	8.0 - 10.0	2.81	2.25	14
LK315 RL 2,40	8.0 - 10.0	2.81	2.40	14
LK315 RL 2,73	8.0 - 10.0	2.81	2.73	14
LK315 RL 3,24	8.0 - 10.0	2.81	3.24	14

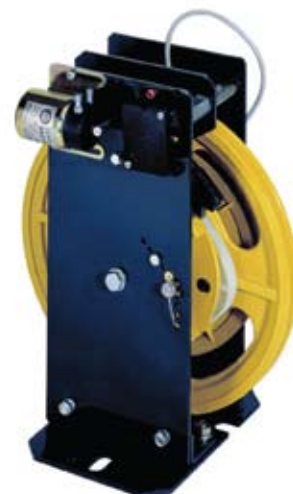

### Please specify the following options:

Remote control with automatic reset -  
12VAC or DC, 24VAC or DC, 48VAC or DC, 110VAC or DC, 230VAC or DC voltages

Mounting base size/distance between holes -  
154 mm, 172 mm, 180 mm

Test groove

Encoder

Other bidirectional and unidirectional governors are available - please call for details.